

# Security Camera Dome/セキュリティカメラ (ドーム型)

## Sub⇔CMOS

Pitch : 2.0mm



**DF51/DF51K Series**

## LED & Camera Module

### Snap Lock Design

3A Max.



**DF57 Series**

4A Max.




**DF61Y Series**

## Main⇔CMOS

### Micro Coaxial


### High-Speed Transmission

Pitch : 0.4mm

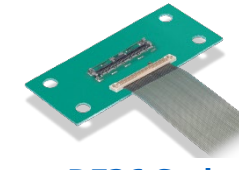

**DF36 Series**

Pitch : 0.5mm

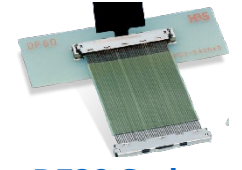

**DF80 Series**

## Ethernet I/O

Cat.6A




**IX Series**

## 5G Antenna

### RF Cable : 5G

Frequency : Up to 30GHz

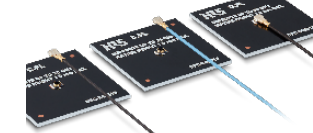


**C.FL Series**

## Main⇔Sub

### Wide Variation, Floating & High Speed Transmission

16Gbps

 
Pitch : 0.8mm  
**FunctionMAX**



**FX18 Series**

16Gbps

Pitch : 0.5mm  
**FunctionMAX**

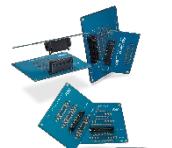

**FX23/FX23L Series**

## RF I/O

### RF I/F : 75Ω


Frequency :  
Up to 12GHz



**BNC75 Series**

### RF Cable : 75Ω

Frequency :  
Up to 12GHz

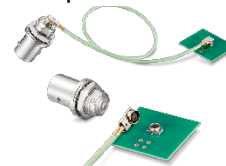


**D.FL75 Series**

## Motor

### Positive Lock Design


Pitch : 1.0mm

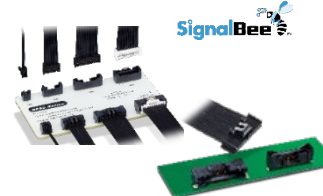

**DF50/DF50A Series**

### Friction Lock Design

Pitch : 2.0mm

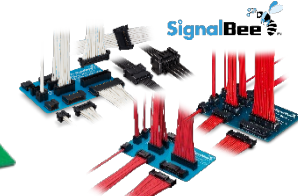

**DF51/DF51K Series**

### Friction Lock Design

Pitch : 0.6mm



**DF53 Series**

Pitch : 0.8mm




**DF52 Series**

# Security Camera Box / セキュリティカメラ (ボックス型)

## Ethernet

Cat.6A

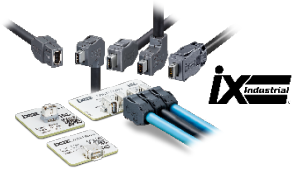

**IX Series**

## RF I/F : 75Ω


Frequency :  
Up to 12GHz



**BNC75 Series**

## microSD™

Push-Push Type,  
Height : 1.15mm

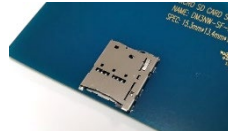

**DM3N Series**

## RF Cable : 75Ω


Frequency :  
Up to 12GHz



**D.FL75 Series**

## RF Cable : 5G

Frequency :  
Up to 30GHz

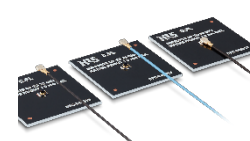

**C.FL Series**

## Snap Lock Design

3A Max.




**DF57 Series**

4A Max.




**DF61Y Series**

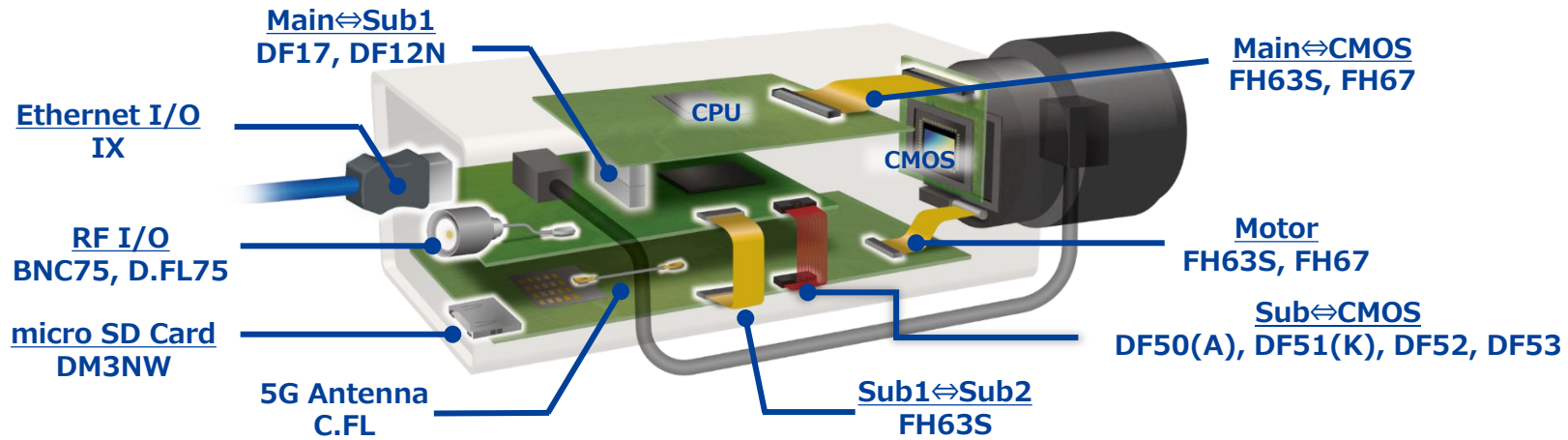


## Wide Variation

 Pitch : 0.5mm  
Height : 3.0-5.0mm



**DF12N Series**

Pitch : 0.5mm  
Height : 4.0-8.0mm

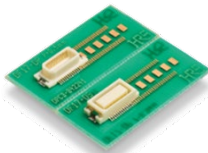

**DF17 Series**


## One Action Lock

Horizontal  
Pitch : 0.5mm  
**OneAction FH™**



**FH63S Series**

Vertical  
Pitch : 0.5mm  
**OneAction FH™**

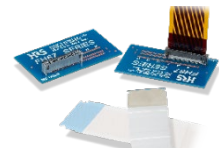

**FH67 Series**

## Friction Lock Design

Pitch : 0.6mm



**DF53 Series**


Pitch : 0.8mm



**DF52 Series**


## Positive Lock Design

Single/Double Row  
Pitch : 1.0mm

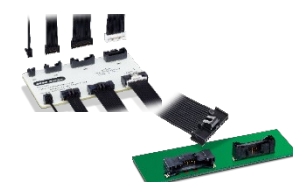

**DF50/DF50A Series**

Double Row  
Pitch : 2.0mm

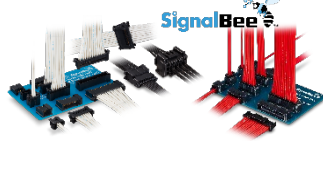


**DF51/DF51K Series**


# Security Camera

## Microphone / Speaker

Low Profile : 1.0mm  
3A

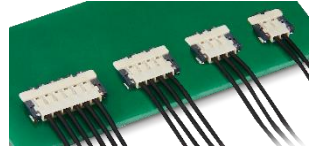

[DF58 Series](#)

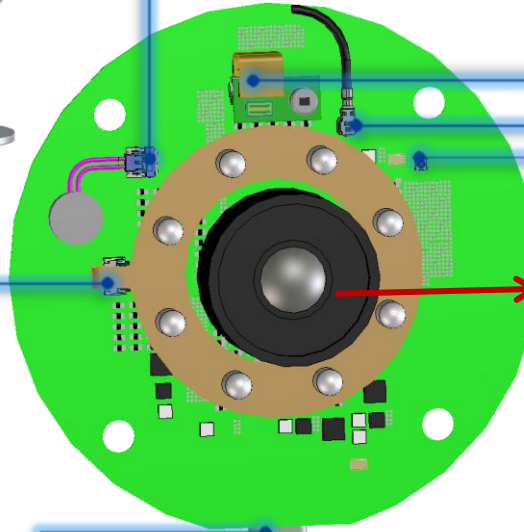


## Sensors

Standard ZIF  
Pitch : 0.5mm

Standard  
Board/FPC-to-Board  
Pitch : 0.35mm



[FH34 Series](#)

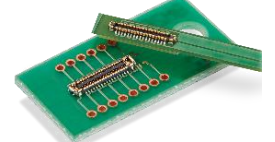

[BM28 Series](#)


## Antenna

Standard RF

RF Switch




[U.FL\(A\) Series](#)

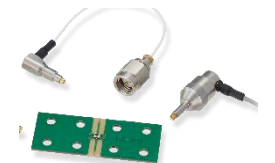

[MS-180 Series](#)

## LED

One Action  
Pitch : 0.25/0.3mm

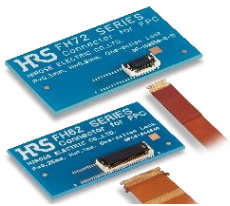

[FH62/FH72 Series](#)

## Interface


USB Type-C, 6A Max.  
Waterproof Available



[CX Series](#)

## Battery \*If available

Power & Signal Hybrid  
10A

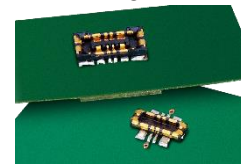

[BM25 Series](#)

## Camera

Standard  
Height : 1.5-7.0mm



[DF40 Series](#)